

Model 309MR

Current Transformer with Multi-Ratio Window Diameter 5.75"

Application

Relaying.

Frequency

50-400 Hz.

Insulation Level

600 Volt, 10 kV BIL full wave.

Terminals are brass screws No. 10-32 with one flatwasher and lockwasher.

The transformer winding is arranged so that the turns are fully distributed between all taps.

Order mounting bracket kit 0221B01525 separately.

Approximate weight 62 lbs.

Excitation data available upon request.




Model 309MR

Catalog Number	Relay Class	Continuous Thermal Rating Factor	
		@ 30 °C	@ 55 °C
309-601MR	C200	2.0	2.0
309-122MR	C400	2.0	1.5
309-202MR	C800	1.5	1.0
309-302MR	C800	1.0	0.8
309-402MR	C800	1.0	0.8

REGULATORY AGENCY APPROVALS

 E93779  LR89403

Manufactured to meet the requirements of ANSI/IEEE C57.13.
Classified by U.L. in accordance with IEC 44-1

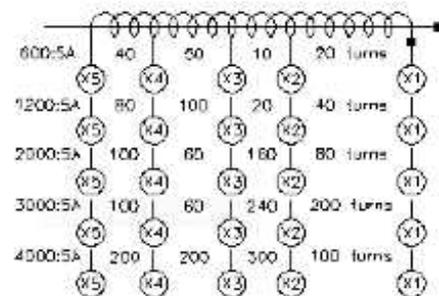

CONNECTION DIAGRAM



